




## SINGLE DEVICE HANDY BOXES & EXTENSION RINGS

4 in. x 2 in. Handy Boxes, 1-1/2 in. Deep - Welded with Conduit KO's

A44

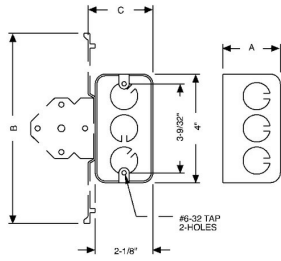

Catalog #: 650

### APPLICATIONS

RACO® Handy boxes, also called utility boxes, are used for convenience outlets, switch boxes or small junction boxes

### PRODUCT FEATURES

N/A

### UL LISTED

File E 195978

### COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at [www.ul.com](http://www.ul.com)

MSDS

[www.hubbell-rtb.com/certifications/Hubbell-RACO\\_MSDS\\_for\\_Steel\\_Boxes\\_and\\_Covers.pdf](http://www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_Steel_Boxes_and_Covers.pdf)

### FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

### GENERAL PRODUCT INFORMATION

Wiring System: Conduit  
Country of Origin: USA

### CONFIGURATION

End Knockouts: (2) 1/2 in.  
Drawn or Welded: Welded  
Raised Ground: No  
Side Knockout(s): (6) 1/2 in.  
Bottom Knockout(s): (3) 1/2 in.

### DRAWING DIMENSIONS

Dimension A: 1-1/2 in.

### PRODUCT MEASUREMENTS

Depth: 1-1/2 in.  
Cubic Inches (cm3): 11.5 (188.5)  
Wt. Ea. (Lbs.): 0.471  
Product Length (in.): 1.56  
Product Width (in.): 4.00  
Product Height (in.): 2.13

### PACKAGING

Minimum Pack Qty.: 50  
Std. Pkg.: 50  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 47.10  
Ship Carton Length (in.): 11.25  
Ship Carton Width (in.): 8.50  
Ship Carton Height (in.): 8.50  
Ctn Weight (Lbs.): 23.55  
Pallet Qty: 5000  
UPC Number: 050169906507  
I2of5: 50050169906502