

Female test connector - PSB 4/7/6 - 0303299

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Female test connector, Color: silver

The illustration shows various versions of the article

Why buy this product

- Test sockets PSB ... are used for a reliable test connection
- With PSB 3/10/4 and PSB 4/7/6, the test connection is provided by the miniature test plug MPS with a 2.3 mm diameter
- All test sockets are screwed into the bridge shaft

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 017918 000417
GTIN	4017918000417
Weight per Piece (excluding packing)	2.120 g
Custom tariff number	85366990
Country of origin	Poland

Technical data

Dimensions

Length	6 mm
Width	6 mm
Pin diameter	4.1 mm

General

Female test connector - PSB 4/7/6 - 0303299

Technical data

General


Color	silver
Ambient temperature (operation)	-40 °C ... 80 °C

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

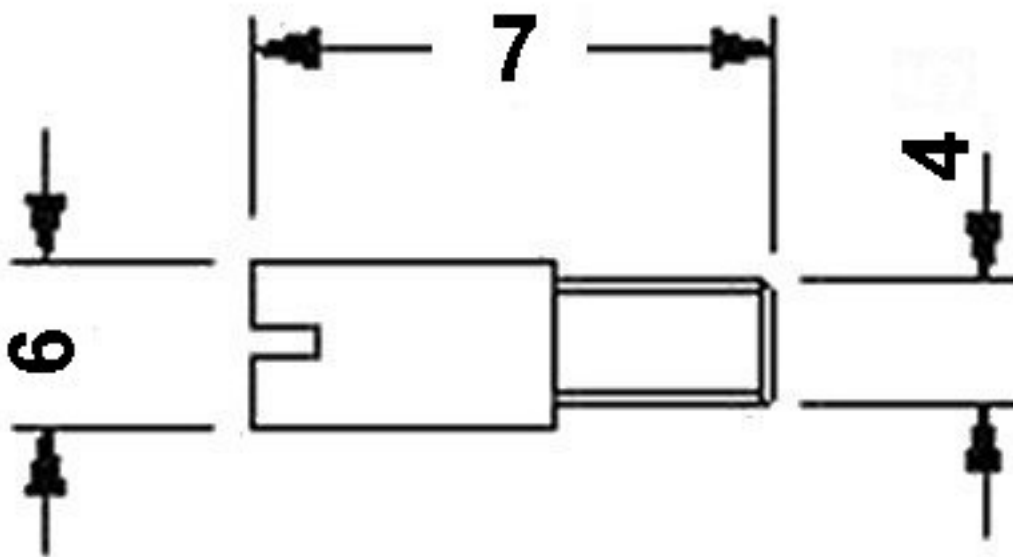

Classifications

eCl@ss

eCl@ss 4.0	27141127
eCl@ss 4.1	27141127
eCl@ss 5.0	27141127
eCl@ss 5.1	27141111
eCl@ss 6.0	27141148
eCl@ss 7.0	27141148
eCl@ss 8.0	27440313
eCl@ss 9.0	27440313

Female test connector - PSB 4/7/6 - 0303299

Classifications

ETIM

ETIM 2.0	EC000897
ETIM 3.0	EC000897
ETIM 4.0	EC002255
ETIM 5.0	EC002255
ETIM 6.0	EC002255

UNSPSC

UNSPSC 6.01	30211812
UNSPSC 7.0901	39121410
UNSPSC 11	39121411
UNSPSC 12.01	39121411
UNSPSC 13.2	39121410

Approvals

Approvals


Approvals

EAC / EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	---	---------------------

EAC		EAC-Zulassung
-----	---	---------------