

PROHEAT® Dualtemp™ Heat Gun

MODEL PH-2100
FEATURES:

- **A GENERAL PURPOSE HEAT GUN.**
Delivers cost effective heat for basic heat applications.
- **TWO HEAT SETTINGS, 260°C & 540°C.** Meets temperature requirements for most materials.
- **PROFESSIONAL QUALITY PERFORMANCE.**
Activates adhesives, bends plastics and dry filler material, shrinks tubing and for many other applications that need a fast, portable heat source.
- **AVAILABLE IN A PROFESSIONAL KIT.**
PH-1100K features a rugged storage / carrying case, Shrink attachment No. 35017 and Spreader attachment No. 35016.



PROHEAT® Quick-Touch™ Heat Gun

MODEL PH-2000
FEATURES:

- **QUICK-TOUCH MOMENTARY CONTACT SWITCH.**
Quickly turns unit on by depressing switch. Heat gun turns off when switch is released.
- **EASY GRIP HANDLE.**
Balanced, ergonomic design prevents operator fatigue.
- **CONVENIENT HANGING LOOP.**
Easy to hang and use with balancers.
- **PROFESSIONAL QUALITY PERFORMANCE.**
Perfect for shrink packaging and many other applications.



Strip Paint



PH-2100K Professional Kit
with 2 versatile attachments




Shrink Packaging

ORDERING INFORMATION

Model No.	Description
PH-2000	Proheat Quick-Touch Heat Gun
PH-2100	Proheat DualTemp Heat Gun
PH-2100K	Proheat DualTemp Heat Gun Kit

Note: For 230 Volt Proheat Series Heat Guns destined outside North America, add suffix A1 or A6 to model number to designate plug type.

Example: PH-2100-A1 (Continental Europe & others)
PH-2100-A6 (UK & others)

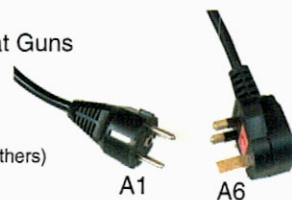

SPECIFICATIONS

Temperature: PH-2100: 260°C or 540°C (500°F or 1,000°F) / PH-2000 540°C (1,000°F)	
Volts: 230VAC / 50/60Hz, 6.2 Amps Max.	Output: 1426W
Air Volume: 453 L/Min. (16 CFM)	Air Velocity: 1219m/min. (4000 FPM)
Nozzle Opening: 22.35mm Dia. (.88")	Nozzle Diameter: 33.27mm Dia. (1.31")
Element: Enclosed Ceramic	Warranty: One Year Limited
Motor: Permanent Magnet	Cordset: 1.82m, 3-wire grounded
Switch: PH-1100: 3 position rocker (Off - Hot 1 - Hot 2) / PH1000 - Momentary Contact, (Off-On)	
Dimensions: 21.6cmx7.6cmx18.5cm (8.2"x3.0"x7.3") (L x W x H)	Net Weight Tool: .73kg (1.6Lbs.)
Single Pack: Dimensions: 24.1cmx22.9cmx7.6cm (9.5"x9"x3") (L x W x H)	Weight: 1.36kg (3 Lbs.)
Single Kit Pack: Dimensions: 38.1cmx42.4cmx8.9cm (15"x16.7"x3.5") (L x W x H)	Weight: 3.18kg (7Lbs.)

Users should independently evaluate the suitability of the product for their application.