 



Silencer

U-1/8-B-NPT

Part number: 12638

FESTO

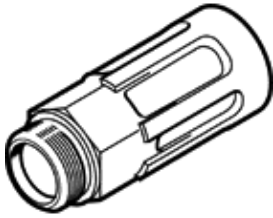

Data sheet

Feature	Value
Assembly position	Any
Operating pressure complete temperature range	0 ... 10 bar
Flow rate to atmosphere	1,450 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Sound pressure level	74 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	8 g
Pneumatic connection	NPT1/8-27
Material of silencer insert	PE
Material of threaded plug	Aluminum
Materials note	Free of copper and PTFE Conforms to RoHS
Material housing	Aluminum