


Socket connector MSSD-EB

Part number: 151687

★ Core product range

FESTO

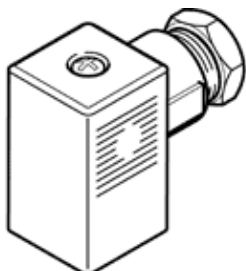

Data sheet

Feature	Value
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	11 g
Electrical connection	Plug socket Plug socket angled Rectangular design, MSEB Rectangular design, MSN2 Per DIN EN 175301-803 According to DIN EN 61984 Plug pattern type C to EN 175301-803 3-pin
Nominal operating voltage DC	300 V
Nominal operating voltage, AC	250 V
Permissible current load	6 A
Surge strength	4 kV
Cable gland connection	Pg7
Cable diameter	6 ... 8 mm
Permissible cable diameter	7.5 mm
Nominal conductor cross-section	$\leq 0.75 \text{ mm}^2$
Terminal cross-section	0.75 mm ²
Protection class	IP65 to IEC 60529
Ambient temperature	-45 ... 90 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Degree of contamination	3
Material housing	Plastic
Housing color	Black
Material seals	NBR