


# Push-in connector QS-16

Part number: 153036

★ Core product range

FESTO

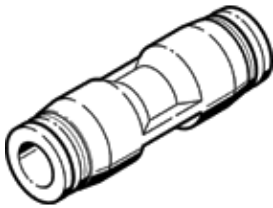

## Data sheet

Feature	Value
Size	Standard
Nominal size	13.7 mm
Assembly position	Any
Container size	1
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 6 bar
Temperature dependent working pressure	-0.95 ... 14 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 80 °C
Maritime classification	see certificate
Product weight	25 g
Pneumatic connection, port 1	for tubing, 16mm outside diameter
Pneumatic connection, port 2	For tubing outside diameter 16 mm
color of release ring	blue
Materials note	Conforms to RoHS
Material housing	PBT
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive