


Blanking plug QSC-6H

Part number: 153268

★ Core product range

FESTO

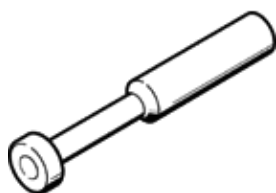

Data sheet

Feature	Value
Size	Standard
Assembly position	Any
Container size	10
Operating pressure complete temperature range	-0.95 ... 6 bar
Temperature dependent working pressure	-0.95 ... 14 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 80 °C
Maritime classification	see certificate
Product weight	0.5 g
Pneumatic connection, port 1	Push-in sleeve QS-6
Materials note	Conforms to RoHS
Material housing	PBT