


Blanking plug QSC-8H

Part number: 153269

★ Core product range

FESTO

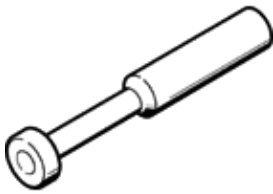

Data sheet

| Feature | Value |
|---|---|
| Size | Standard |
| Assembly position | Any |
| Container size | 10 |
| Operating pressure complete temperature range | -0.95 ... 6 bar |
| Temperature dependent working pressure | -0.95 ... 14 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | -10 ... 80 °C |
| Maritime classification | see certificate |
| Product weight | 1 g |
| Pneumatic connection, port 1 | Push-in sleeve QS-8 |
| Materials note | Conforms to RoHS |
| Material housing | PBT |