 



**Silencer**  
**U-1/4-B-NPT**  
 Part number: 12639

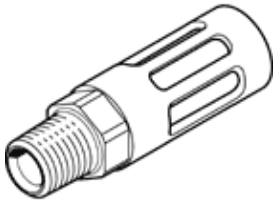

**Data sheet**

Feature	Value
Assembly position	Any
Operating pressure complete temperature range	0 ... 10 bar
Flow rate to atmosphere	3,000 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Sound pressure level	78 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	17 g
Pneumatic connection	NPT1/4-18
Material of silencer insert	PE
Material of threaded plug	Aluminum
Materials note	Free of copper and PTFE Conforms to RoHS
Material housing	Aluminum