 



Silencer U-1/4

Part number: 2316

★ Core product range

FESTO

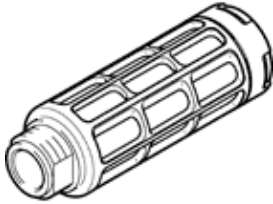

Data sheet

Feature	Value
Assembly position	Any
Working pressure	0 ... 10 bar
Flow rate to atmosphere	3,400 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Sound pressure level	77 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	8 g
Pneumatic connection	G1/4
Material of silencer insert	PE
Materials note	Free of copper and PTFE Conforms to RoHS