 



Silencer U-1/2

Part number: 2310

★ Core product range

FESTO

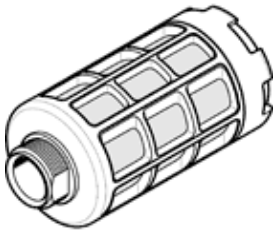

Data sheet

Feature	Value
Assembly position	Any
Working pressure	0 ... 10 bar
Flow rate to atmosphere	10,600 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Sound pressure level	80 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	58 g
Pneumatic connection	G1/2
Material of silencer insert	PE
Materials note	Free of copper and PTFE Conforms to RoHS