


Push-in/threaded L-fitting QBML-M5-1/8-U-M

Part number: 533228

FESTO

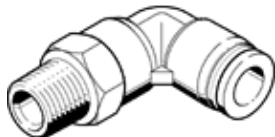

Data sheet

| Feature | Value |
|---|--|
| Size | Standard |
| Nominal size | 0.098 " |
| Type of seal on screw-in stud | Sealing ring |
| Operating pressure complete temperature range | 0 ... 145 Psi |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | 32 ... 140 °F |
| Maritime classification | see certificate |
| Nominal tightening torque | 0.5 Nm |
| Tolerance for nominal tightening torque | ± 10 % |
| Product weight | 0.145 oz |
| color of release ring | Grey |
| Materials note | Conforms to RoHS |
| Material housing | PBT |
| Material of threaded seal | NBR |
| Material release ring | POM |
| Material of tube retaining claw | High alloy steel, non-corrosive |