


Swivel flange SNC-40

Part number: 174384

★ Core product range

FESTO

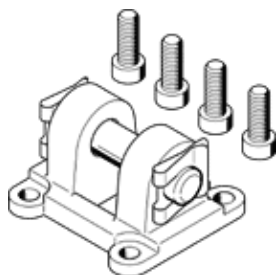

Data sheet

Feature	Value
Size	40
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-40 ... 150 °C
Product weight	140 g
Materials note	Free of copper and PTFE Conforms to RoHS
Material mounting	Aluminum die cast
Material mounting pin	Steel Galvanized
Material screws	Steel Galvanized
Material lock	Spring steel Galvanized