 



# Distributor block MS4N-FRM-FRZ

Part number: 554101

FESTO

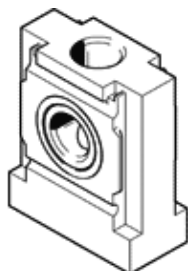

## Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Working pressure	0 ... 14 bar
Standard nominal flow rate in main flow direction 1->2	4,050 l/min
Standard nominal flow rate outlet at top	3,250 l/min
Standard nominal flow rate outlet at bottom	2,900 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Authorization	c UL us - Recognized (OL)
Product weight	60 g
Pneumatic connection, port 3	NPT1/4-18
Pneumatic connection, port 4	NPT1/4-18
Materials note	Free of copper and PTFE Conforms to RoHS
Material housing	Aluminum die cast