


# Electrical sub-base VAVE-L1-1H2-LR

Part number: 566716

★ Core product range

FESTO

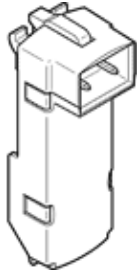

## Data sheet

Feature	Value
Assembly position	Any
Polarity protected	for operating voltage
Additional functions	Spark arresting Reduction of holding current
Signal status display	LED
Nominal operating voltage DC	24 V
Surge strength	0.8 kV
Degree of contamination	3
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Corrosion resistance classification CRC	0 - No corrosion stress
Protection class	IP40
Ambient temperature	-5 ... 60 °C
Authorization	RCM Mark
Product weight	1.5 g
Electrical connection	Plug socket 2-pin
Protective earth connection	Not available
Mounting type	Clip
Housing color	Black
Materials note	Conforms to RoHS
Material housing	PA