


Connecting cable NEBV-S1G25-K-2.5-N-LE25-S6

Part number: 575417

FESTO

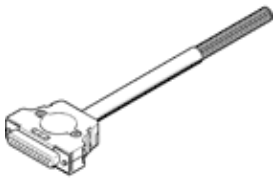

Data sheet

Feature	Value
Mounting type	4-40UNC
Assembly position	Any
Product weight	429 g
Electrical connection	Plug socket Sub-D 25-pin
Operating voltage range DC	<= 30 V
Acceptable current load at 40 °C	2.6 A
Cable length	2.5 m
Cable attribute	For static applications
Min. cable bending radius	122 mm
Cable diameter	10.2 mm
Cable diameter tolerance	± 0,25 mm
Cable structure	25x0,34
Protection class	IP40
Ambient temperature	-5 ... 80 °C
Materials note	Conforms to RoHS
Degree of contamination	2
Corrosion resistance classification CRC	0 - No corrosion stress
Material cable sheath	PVC
Material housing	Reinforced PC
Material electrical contact	Bronze Gold plated