



CSB-M1250M1250-T

SPLITTERS



M12 T Splitter - Passive


5-Pin Female Trunk Straight

5-Pin Female T Branch (1)

5-Pin Male T Branch(1)

Black TPU Splitter Junction

Part Number: 807397

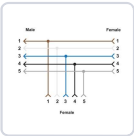

SPECIFICATIONS

IP Rating	IP67
Shield/No Shield	No Shield
Wiring	Parallel
Branches: Genders	Female, Male
Branches: Orientations	Straight, Straight
Splitter: Overmold Material and Color	PUR Black

Trunk Length (m)	0.00
Branches: Number of Contacts	5, 5

Cookies

By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List.

To learn more, visit our [privacy policy](#).

Number of Branches	2
Voltage Rating (V)	250 V ac/dc
Maximum Temp. (Celsius)	105
Current Rating (A)	4.0
Trunk: Orientation	Straight
Trunk: Number of Contacts	5
Trunk: Connector Type	M12
Trunk: Gender	Female
Minimum Temp. (Celsius)	-40
Branches: Connector Types	M12, M12

Cookies

By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List.

To learn more, visit our [privacy policy](#).



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 | United States of America