

Cover plate - HC-B 16-AP-GY - 1660384


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON cover plate, for panel cutouts of type B16/HV6, 3.5 mm thick, gray

RoHS

Key Commercial Data

Packing unit	10 STK
GTIN	 4 017918 022020
GTIN	4017918022020

Technical data

Dimensions

Length	123 mm
Height	3.5 mm
Hole diameter	4.5 mm
Width	52 mm
Drill hole distance, horizontal	103 mm
Drill hole distance, vertical	32 mm

General

Note	For panel cutouts of type B16/HV6
Material	PA
Flammability rating according to UL 94	HB
Color	gray
Type	B16
	HV6

Standards and Regulations

Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

Cover plate - HC-B 16-AP-GY - 1660384


Technical data

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

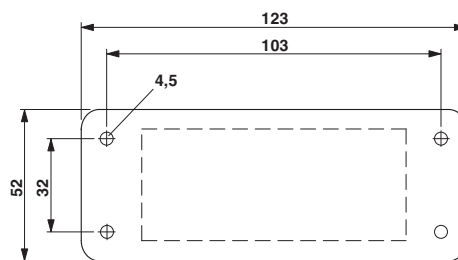

Dimensional drawing

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>