



TEST PROBES

Dimensions & Specifications

▶ QUAD-00 SERIES

0.020 (0.51) Centers

For Quad-00 Series Receptacles see pg. 49

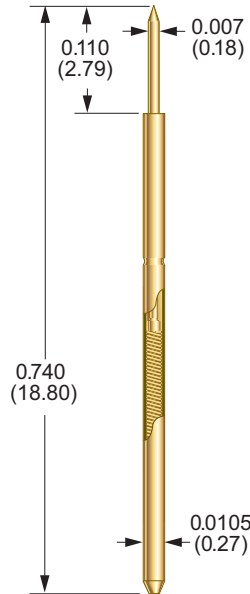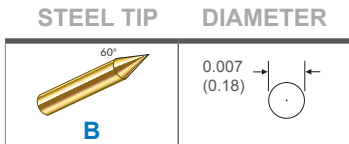




PROBE SPECIFICATIONS

Minimum Centers	0.020 (0.51)
Current Rating	0.30 A continuous
Spring Force	0.75 oz (21 g) @ 0.067 (1.70) travel
Preload Force	0.23 oz (6.5 g)
Typical Resistance	< 160 mΩ
Maximum Travel	0.100 (2.54)
Working Travel	0.067 (1.70)

MATERIALS

Barrel	Gold alloy
Spring	Music wire, gold plated
Plunger	Steel, gold plated over nickel

FIXTURING OPTIONS

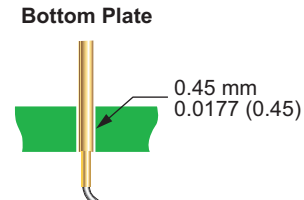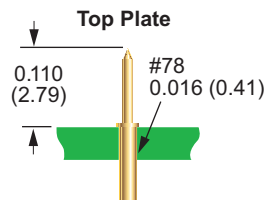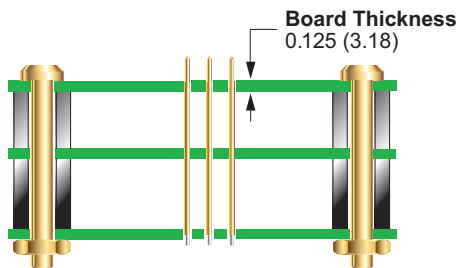

HOW TO ORDER

QUAD - 00 B	
1	2
1 ▶ SERIES	QUAD - 00
2 ▶ TIP STYLE	B