



Exceptional Value  
Improves Lighting Quality  
Reduces Energy Costs



Industrial Grade  
**LED** Task Lights



## Industrial Grade **LED** Task Lights

### Exceptional Value Improves Lighting Quality Reduces Energy Costs

Aven's Industrial Grade LED task lights are ideal for lathes, grinders, presses, assembly, inspection, workbench, office and many other uses. The LED element offers significant increase in intensity over that of a standard 20 watt halogen bulb, while using close to 70% less energy. The light covers also stays cool to touch and the LEDs have a minimum of 20,000 hours of high-output life. These flexible gooseneck work lights can be adjusted to just the right position for easier examination and inspection of close-up work. Each Machine task light comes with an 5 foot (152cm) power cord and the Sirrus task light with a 6 foot (182.88cm) power cord.

### Features

- High intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Flexible Gooseneck Arm for precise positioning





Optional Magnetic Base for Sirrus LED task lights 26526, 26527 and 26528. Magnetic base allows for secure yet mobile placement on magnetic surfaces such as metal benches or cabinets.

| Part #           | Description   | Price           |
|------------------|---|-----------------|
| <b>26526</b>     | SIRRUS LED Task Light w/ Swivel Head, 500mm(19.5") Flex Arm & Mounting Clamp                | <b>\$155.00</b> |
| <b>26527</b>     | Sirrus LED Task Light w/ High Intensity Fixed Focus, 500mm(19.5") Flex Arm & Mounting Clamp | <b>\$99.95</b>  |
| <b>26528</b>     | Sirrus LED Task Lamp, 500mm(19.5") Flex Arm & Mounting Clamp                                | <b>\$149.95</b> |
| <b>26530-LED</b> | Machine Tool LED Task Light w/ Magnetic Base & 18" Flexible Arm                             | <b>\$76.80</b>  |
| <b>26531-LED</b> | Machine Tool LED Task Light Compact with 18" Flexible Arm                                   | <b>\$83.00</b>  |
| <b>26532-LED</b> | Machine Tool LED Task Light Domed with 36" Flexible Arm                                     | <b>\$99.00</b>  |
| <b>26533-LED</b> | Machine Tool LED Task Light Domed with 23" Flexible Arm                                     | <b>\$92.00</b>  |
| <b>26520-MB</b>  | Sirrus Magnetic Base optional for 26526, 26527 and 26528                                    | <b>\$18.95</b>  |



AVEN

500MM(19.5")  
INDUSTRIAL GRADE  
FLEXIBLE GOOSENECK  
COATED ARM

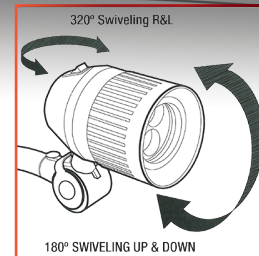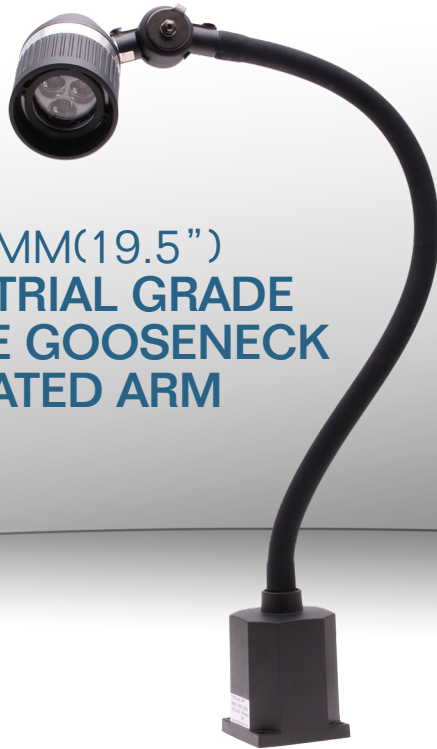

## SIRRUS **LED** Task Light w/ Swivel Head, 500mm Flex Arm and Clamp

### Dramatically Reduces Power Consumption and Improves Lighting Quality

Our new SIRRUS LED Task Light is designed to provide high efficiency & powerful lighting. It features low power consumption with extra long service life. The SIRRUS LED Task Light integrates many outstanding features, making it popular for many locations such as production machines, assembly stations, offices, inspection areas - anywhere precision work is being performed. The swivel head permits swiveling in any direction or sets securely in a fixed position. Includes metal clamp ideal for workbench mounting.

### Features

- 500mm(19.5") industrial grade flexible gooseneck coated arm
- Arm stays set in any position to provide direct light where needed
- High intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Ideal for assembly, workshop or office applications
- Mounting Clamp allows for easy attachment to desk and bench tops

#### SIRRUS LED TASK LIGHT W/ SWIVEL HEAD, 500MM(19.5") FLEX ARM & MOUNTING CLAMP

|                                |   |
|--------------------------------|---|
| <b>LED COLOR</b>               | High intensity white LEDs   |
| <b>LIGHTING CONTROL</b>        | On/Off  |
| <b>LED LIFE</b>                | Minimum 20,000 hours  |
| <b>LED OUTPUT</b>              | 3W  |
| <b>OUTPUT VOLTAGE</b>          | 24V   |
| <b>INPUT VOLTAGE</b>           | 100-277V  |
| <b>LENGTH OF GOOSENECK ARM</b> | 19.5" (500mm)   |
| <b>WEIGHT</b>                  | 5lbs (2.25kg)   |
| <b>PACKAGE CONTENTS</b>        | 1 ea. SIRRUS Task Light LED w/ Swivel Head, 500mm Flex Arm & Mounting Clamp |

| Part #          | Description  | Price           |
|-----------------|--|-----------------|
| <b>26526</b>    | SIRRUS LED Task Light w/ Swivel Head, 500mm(19.5") Flex Arm & Mounting Clamp | <b>\$155.00</b> |
| <b>26520-MB</b> | SIRRUS Magnetic Base optional for 26526, 26527 and 26528                     | <b>\$18.95</b>  |

## 500MM(19.5") INDUSTRIAL GRADE FLEXIBLE GOOSENECK COATED ARM



## SIRRUS **LED** Task Light w/ High Intensity Fixed Focus, 500mm Flex Arm and Clamp

### Dramatically Reduces Power Consumption and Improves Lighting Quality

Our new SIRRUS LED Task Light is designed to provide high efficiency & powerful lighting. It features low power consumption with extra long service life. The SIRRUS LED Task Light integrates many outstanding features making it popular for many locations such as machines, assembly stations, office & inspection locations and precision working. The soft, even area illumination is ideal for close-up applications that require more than a focused beam. Output ranges from 4100 lux at 1 foot distance to 1070 lux at 2 feet. The protective switch cover prevents permeation by dust, water, lubricants, coolants, and other liquids. Includes metal clamp ideal for workbench mounting.

### Features

- 500mm(19.5") industrial grade flexible gooseneck coated arm
- Arm stays set in any position to provide direct light where needed
- High intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Ideal for assembly, workshop or office applications
- Mounting Clamp allows for easy attachment to desk and bench tops

### SIRRUS LED TASK LIGHT W/ HIGH INTENSITY FIXED FOCUS, 500MM(19.5") FLEX ARM & MOUNTING CLAMP

|                                |   |
|--------------------------------|---|
| <b>LED COLOR</b>               | High intensity white LEDs   |
| <b>LIGHTING CONTROL</b>        | On/Off  |
| <b>LED LIFE</b>                | Minimum 20,000 hours  |
| <b>LED OUTPUT</b>              | 3W  |
| <b>OUTPUT VOLTAGE</b>          | 24V   |
| <b>INPUT VOLTAGE</b>           | 100-277V  |
| <b>LENGTH OF GOOSENECK ARM</b> | 19.5" (500mm)   |
| <b>WEIGHT</b>                  | 5lbs (2.25kg)   |
| <b>PACKAGE CONTENTS</b>        | 1 ea. SIRRUS Task Light LED High Intensity Fixed Focus with 500mm Flex Arm & Mounting Clamp |

| Part #          | Description   | Price          |
|-----------------|---|----------------|
| <b>26527</b>    | SIRRUS LED Task Light w/ High Intensity Fixed Focus, 500mm(19.5") Flex Arm & Mounting Clamp | <b>\$99.95</b> |
| <b>26520-MB</b> | SIRRUS Magnetic Base optional for 26526, 26527 and 26528                                    | <b>\$18.95</b> |



## 500MM(19.5") INDUSTRIAL GRADE FLEXIBLE GOOSENECK COATED ARM



## SIRRUS **LED** Lamp, 500mm Flex Arm & Mounting Clamp

### Get Light Where You Need it most?

The innovative SIRRUS LED Lamp features a flexible arm that allows you to direct light exactly where you want it. The 500mm (19.5") Flex Arm, covered with an insulated sleeve, provides vibration resistance. With its slim aluminum lamp head and one piece fabricated PC front shade, this energy efficient LED lamp provides an elegant modern design ideal for use anywhere including many office applications, assembly workstations, or quality inspection areas. You can regulate the brightness of the LED light with a convenient built-in dimmer switch on the base of the lamp. Includes metal clamp ideal for workbench mounting.

### Features

- 500mm(19.5") industrial grade flexible gooseneck coated arm
- Arm stays set in any position to provide direct light where needed
- High intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Ideal for assembly, workshop or office applications
- Mounting Clamp allows for easy attachment to desk and bench tops

| SIRRUS LED LAMP, 500MM(19.5) FLEX ARM & MOUNTING CLAMP |  |
|--|--|
| <b>LED COLOR</b>                                       | High intensity white LEDs                              |
| <b>LIGHTING CONTROL</b>                                | On/Off   |
| <b>LED LIFE</b>  | Minimum 20,000 hours                                   |
| <b>LED OUTPUT</b>                                      | 14W  |
| <b>OUTPUT VOLTAGE</b>                                  | 12V  |
| <b>INPUT VOLTAGE</b>                                   | 100-260V   |
| <b>LENGTH OF GOOSENECK ARM</b>                         | 19.5" (500mm)  |
| <b>WEIGHT</b>  | 5lbs (2.25kg)  |
| <b>PACKAGE CONTENTS</b>                                | 1 ea. SIRRUS Lamp LED, 500mm Flex Arm & Mounting Clamp |

| Part #          | Description  | Price           |
|-----------------|--|-----------------|
| <b>26528</b>    | SIRRUS LED Lamp, 500mm(19.5") Flex Arm & Mounting Clamp  | <b>\$149.95</b> |
| <b>26520-MB</b> | SIRRUS Magnetic Base optional for 26526, 26527 and 26528 | <b>\$18.95</b>  |



## Machine Tool **LED** Task Light w/ Magnetic Base & 18" Flexible Arm

### Magnetic base allows versatile mounting options for ideal illumination

This LED machine tool task light is ideal for lathes, grinders, presses, assembly, inspection, and many other uses in the shop. It has a durable metal shade with a black finish. The LED element offers significant increase in intensity over that of a standard 20 watt halogen bulb, while using close to 70% less energy. The metal shade also stays cool to touch and the LEDs have a minimum of 20,000 hours of high-output life. The 18" (457mm) flexible arm holds firmly for precise positioning and the magnetic base allows you to securely mount the task light to most metal surfaces. Comes with an 5 foot (152cm) power cord.

### Features

- Durable metal shade with black finish
- 24 high intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Strong magnetic base
- Flexible Arm for precise positioning

#### MACHINE TOOL LED TASK LIGHT WITH MAGNETIC BASE & 18" FLEXIBLE ARM

|                              |  |
|------------------------------|--|
| <b>LED COLOR</b>             | 24 high intensity white SMD LEDs               |
| <b>LIGHTING CONTROL</b>      | On/Off   |
| <b>LED COLOR TEMPERATURE</b> | 4000K  |
| <b>LED LIFE</b>              | Minimum 20,000 hours                           |
| <b>LED OUTPUT</b>            | 6.5W   |
| <b>OUTPUT VOLTAGE</b>        | 12V  |
| <b>INPUT VOLTAGE</b>         | 100-240V                                       |
| <b>LENGTH OF GOOSENECK</b>   | 18" (464mm)                                    |
| <b>DIAMETER OF LAMPSHADE</b> | 4" (102mm)                                     |
| <b>ADAPTER</b>               | 24V, 0.5A                                      |
| <b>WEIGHT</b>                | 2.2 lbs (998g)                                 |
| <b>PACKAGE CONTENTS</b>      | Machine Tool LED Task Light with Power Adapter |

| Part #           | Description  | Price          |
|------------------|--|----------------|
| <b>26530-LED</b> | <b>Machine Tool LED Task Light w/ Magnetic Base &amp; 18" Flexible Arm</b> | <b>\$76.80</b> |



## Machine Tool **LED** Task Light Compact w/ 18" Flexible Arm

### Compact metal lamp head for unobstructed view of work area for ideal illumination



This compact LED machine tool task light has a small compact head to fit in tight areas and is ideal for medium duty applications. The LED element offer significant increase in intensity over that of a standard 20 watt halogen bulb, while using close to 70% less energy. The head also stays cool to touch and the LEDs have a minimum of 20,000 hours of high-output life. The 18" (457mm) flexible arm holds firmly for precise positioning. It also has a permanent steel bracket for horizontal or vertical mounting. Comes with an 5 foot (152cm) power cord.

### Features

- Compact lamp shade with black exterior
- 10 high intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)

| MACHINE TOOL LED TASK LIGHT COMPACT WITH 18" FLEXIBLE ARM |  |
|---|--|
| LED COLOR   | 10 high intensity white SMD LEDs               |
| LIGHTING CONTROL  | On/Off   |
| LED COLOR TEMPERATURE                                     | 4000K  |
| LED LIFE  | Minimum 20,000 hours                           |
| LED OUTPUT  | 6.5W   |
| OUTPUT VOLTAGE  | 12V  |
| INPUT VOLTAGE   | 100-240V                                       |
| LENGTH OF GOOSENECK                                       | 18" (464mm)                                    |
| DIAMETER OF LAMPSHADE                                     | 2.25" (57mm)                                   |
| ADAPTER   | 24V, 0.5A                                      |
| WEIGHT  | 1.4lbs (635g)                                  |
| PACKAGE CONTENTS  | Machine Tool LED Task Light with Power Adapter |

| Part #    | Description   | Price   |
|-----------|---|---------|
| 26531-LED | Machine Tool LED Task Light Compact with 18" Flexible Arm | \$83.00 |

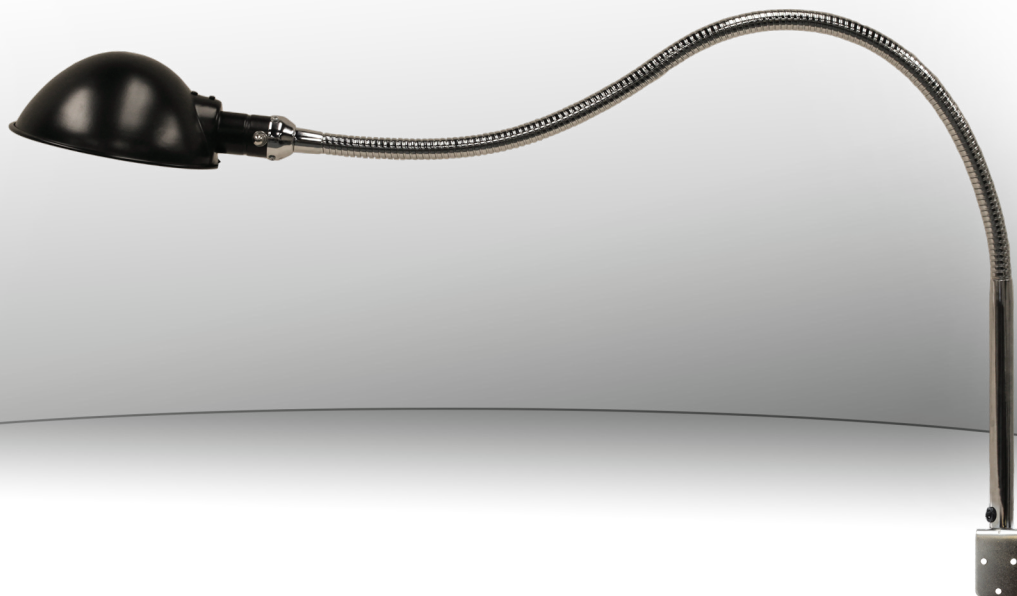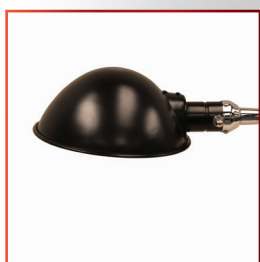

## Machine Tool **LED** Task Light Domed w/ 36" Flexible Arm

### Provides illumination over a large surface area

Our domed machine tool task light is ideal for lathes, grinders, presses, assembly, inspection, and many other uses in the shop. The LED element offer significant increase in intensity over that of a standard halogen bulb, while using close to 70% less energy. The head also stays cool to touch and the LEDs have a minimum of 20,000 hours of high-output life. The 36" (898mm) flexible arm holds firmly for precise positioning. It also has a permanent steel bracket for horizontal or vertical mounting. Comes with an 5 foot (152cm) power cord.


### Features

- Domed metal shade with black finish
- 36 high intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Flexible arm for precise positioning
- Provides illumination over a large surface area

#### MACHINE TOOL LED TASK LIGHT DOMED W/ 36" FLEXIBLE ARM

|                              |  |
|------------------------------|--|
| <b>LED COLOR</b>             | 36 high intensity white SMD LEDs               |
| <b>LIGHTING CONTROL</b>      | On/Off   |
| <b>LED COLOR TEMPERATURE</b> | 4000K  |
| <b>LED LIFE</b>              | Minimum 20,000 hours                           |
| <b>LED OUTPUT</b>            | 7.7W   |
| <b>OUTPUT VOLTAGE</b>        | 12V  |
| <b>INPUT VOLTAGE</b>         | 100-240V                                       |
| <b>LENGTH OF GOOSENECK</b>   | 36" (898mm)                                    |
| <b>DIAMETER OF LAMPSHADE</b> | 6.6" (167mm)                                   |
| <b>ADAPTER</b>               | 24V, 0.5A                                      |
| <b>WEIGHT</b>                | 3lbs (.4kg)                                    |
| <b>PACKAGE CONTENTS</b>      | Machine Tool LED Task Light with Power Adapter |

| Part #           | Description  | Price          |
|------------------|--|----------------|
| <b>26532-LED</b> | <b>Machine Tool LED Task Light Domed with 36" Flexible Arm</b> | <b>\$99.00</b> |

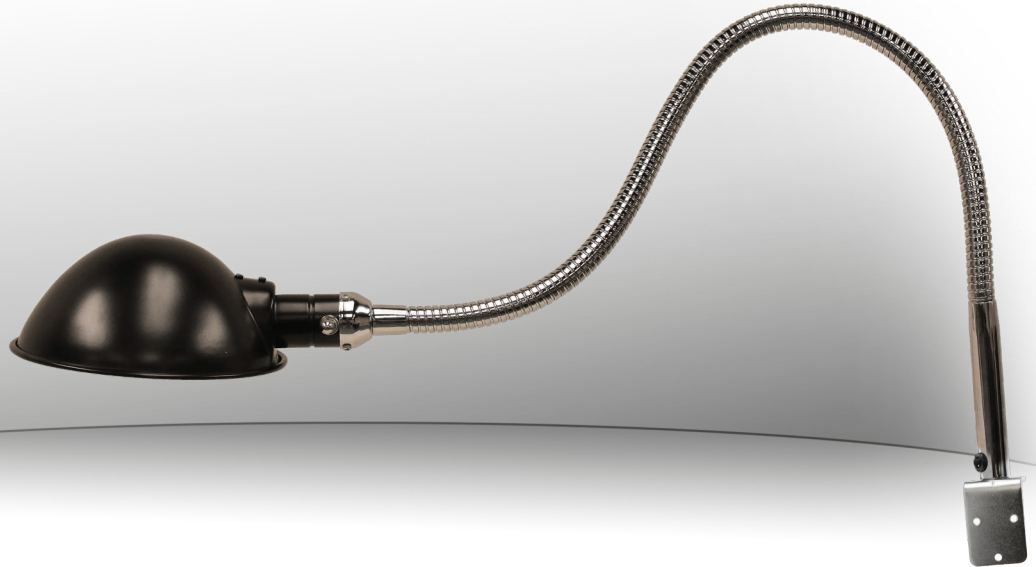

## Machine Tool **LED** Task Light Domed w/ 23" Flexible Arm

### Provides illumination over a large surface area

Our domed machine tool task light is ideal for lathes, grinders, presses, assembly, inspection, and many other uses in the shop. The LED element offer significant increase in intensity over that of a standard halogen bulb, while using close to 70% less energy. The head also stays cool to touch and the LEDs have a minimum of 20,000 hours of high-output life. The 23" (584mm) flexible arm holds firmly for precise positioning. It also has a permanent steel bracket for horizontal or vertical mounting. Comes with an 5 foot (152cm) power cord.

### Features

- Domed metal shade with black finish
- 36 high intensity energy saving LEDs
- Cool operating temperature
- Exceptionally long LED element life (minimum 20,000 hours)
- Flexible arm for precise positioning
- Provides illumination over a large surface area

#### MACHINE TOOL LED TASK LIGHT DOMED W/ 23" FLEXIBLE ARM

|                              |  |
|------------------------------|--|
| <b>LED COLOR</b>             | 36 high intensity white SMD LEDs               |
| <b>LIGHTING CONTROL</b>      | On/Off   |
| <b>LED COLOR TEMPERATURE</b> | 4000K  |
| <b>LED LIFE</b>              | Minimum 20,000 hours                           |
| <b>LED OUTPUT</b>            | 7.7W   |
| <b>OUTPUT VOLTAGE</b>        | 12V  |
| <b>INPUT VOLTAGE</b>         | 100-240V                                       |
| <b>LENGTH OF GOOSENECK</b>   | 23" (584mm)                                    |
| <b>DIAMETER OF LAMPSHADE</b> | 6.6" (167mm)                                   |
| <b>ADAPTER</b>               | 24V, 0.5A                                      |
| <b>WEIGHT</b>                | 3lbs (.4kg)                                    |
| <b>PACKAGE CONTENTS</b>      | Machine Tool LED Task Light with Power Adapter |

| Part #           | Description  | Price          |
|------------------|--|----------------|
| <b>26533-LED</b> | <b>Machine Tool LED Task Light Domed with 23" Flexible Arm</b> | <b>\$92.00</b> |