


Adapter
AD-G1/8-1/8NPT-I
Part number: 9395

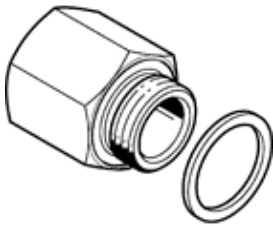

Data sheet

Feature	Value
Nominal size	5.95 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	6 Nm
Max. tightening torque, pneumatic connection 2	7 Nm
Nominal tightening torque	10.55 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	10.38 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	NPT1/8-27
Materials note	Conforms to RoHS