


Adapter AD-G1/4-1/4NPT-I

Part number: 9396

FESTO

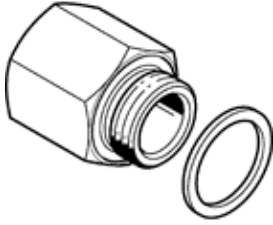

Data sheet

Feature	Value
Nominal size	7.95 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	11 Nm
Max. tightening torque, pneumatic connection 2	12 Nm
Nominal tightening torque	9.05 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	24.22 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	NPT1/4-18
Materials note	Conforms to RoHS