


# Adapter AD-G1/2-1/2NPT-I

Part number: 9398

FESTO

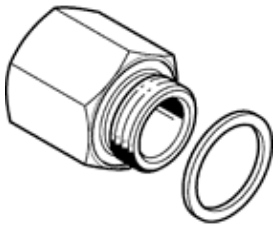

## Data sheet

Feature	Value
Nominal size	14.3 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	40 Nm
Max. tightening torque, pneumatic connection 2	28 Nm
Nominal tightening torque	47.9 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	51.89 g
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	NPT1/2-14
Materials note	Conforms to RoHS