


Adapter AD-1/4NPT-G1/4-I

Part number: 9625

FESTO

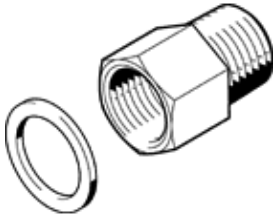

Data sheet

Feature	Value
Nominal size	7.95 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	12 Nm
Max. tightening torque, pneumatic connection 2	11 Nm
Product weight	21 g
Pneumatic connection, port 1	NPT1/4-18
Pneumatic connection, port 2	G1/4
Materials note	Conforms to RoHS