


Adapter
AD-3/8NPT-G3/8-I
Part number: 9626

FESTO

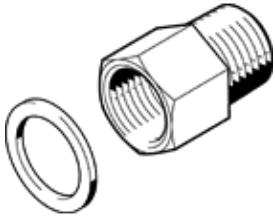

Data sheet

Feature	Value
Nominal size	11.5 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	22 Nm
Max. tightening torque, pneumatic connection 2	25 Nm
Product weight	25.98 g
Pneumatic connection, port 1	NPT3/8-18
Pneumatic connection, port 2	G3/8
Materials note	Conforms to RoHS