


Adapter AD-1/2NPT-G1/2-I

Part number: 9627

FESTO

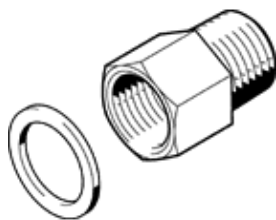

Data sheet

| Feature | Value |
|--|--------------------------|
| Nominal size | 14.3 mm |
| Operating pressure complete temperature range | -0.95 ... 10 bar |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | -10 ... 60 °C |
| Max. tightening torque, pneumatic connection 1 | 28 Nm |
| Max. tightening torque, pneumatic connection 2 | 40 Nm |
| Product weight | 48.48 g |
| Pneumatic connection, port 1 | NPT1/2-14 |
| Pneumatic connection, port 2 | G1/2 |
| Materials note | Conforms to RoHS |