



ENGLISH

Datasheet

Stock No:
RS Pro



Product Description : SMD Common Mode Choke

Schematic



Electrical Specification@25°C

RS Stock Code	OCL (μH) +50/-30%	LL (μH) (typ)	Rcu m Ω (typ)	Turns Ratio	VT (Vrms)
1048405	100	0.30	400	1:1:1:1	500
1048406	1000	0.35	350	1:1:1:1	500
1048407	47	0.25	230	1:1:1:1	500
1048408	4700	0.70	980	1:1:1:1	500


Operating Temperature -25°C to +85°C

Test Frequency:
Nominal Inductance Measured @100KHz/20mV
Leakage Inductance Measured @100KHz/100mV




Mechanical Specification


ENGLISH

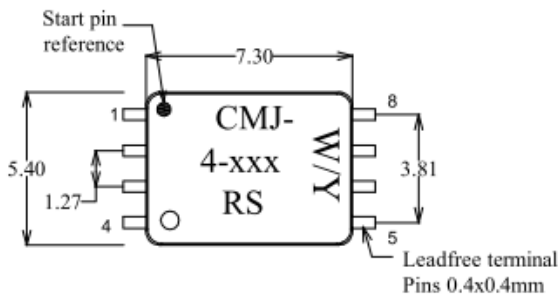


Top View

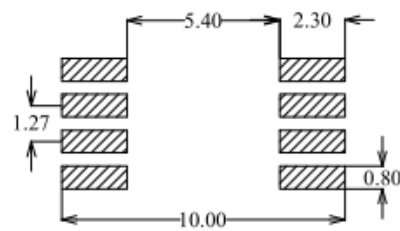

Suggested Pad Layout

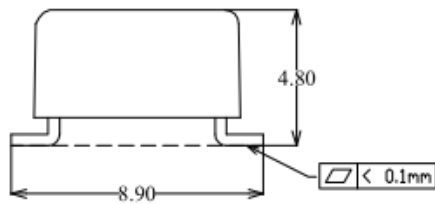


Front View

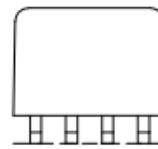

Left Side View

Unit : mm Dimension tolerance : $\pm 0.25\text{mm}$ (Unless specified) Pin pitch tolerance : $\pm 0.10\text{mm}$

CMJ-4-xxx IZI Performance

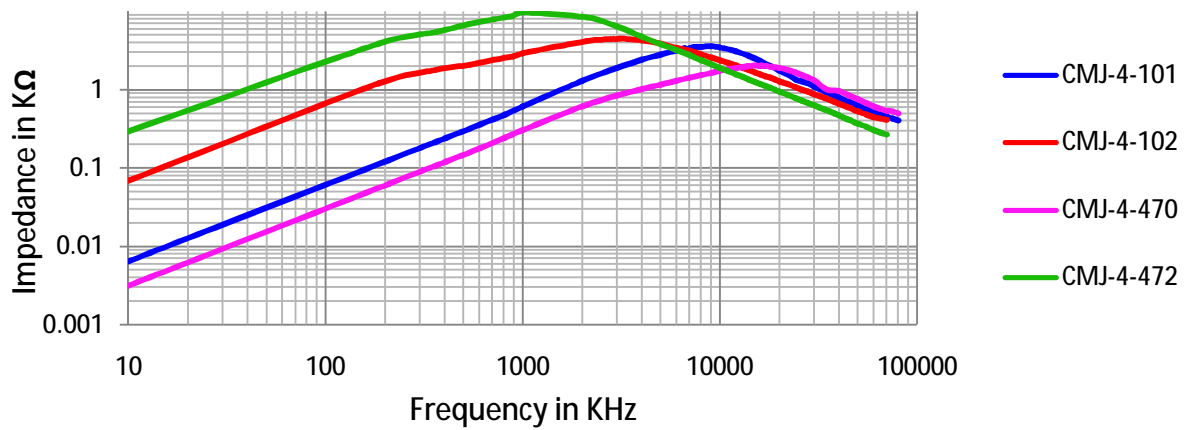

Date: 6.07.2016 Issue : 01