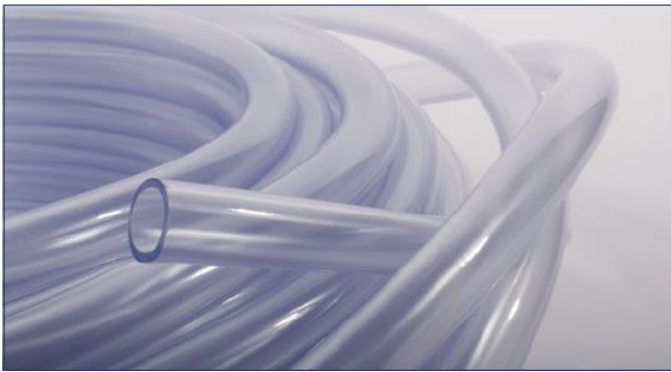


Datasheet

Stock No: 9145506**RS Pro Clear Unreinforced PVC Hose**

Nominal Size	10 x 13mm
Internal Diameter	10.0 ± 0.25mm
External Diameter	13.0 ± 0.25mm
Length Tolerance	BS EN ISO 1307 (± 1%)
Maximum Working Pressure	N/A
Minimum Burst Pressure	N/A
Bend Radius	117mm
Working Temperature	-15°C to +60°C
Material	Flexible PVC
Material Softness	BSS45 FDA Approved
Flammability	Self Extinguishing
Weight Per Meter	0.078Kg
Coil Weight	2.34Kg