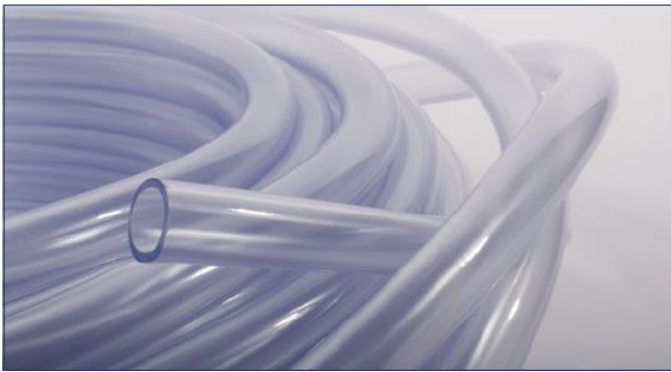


Datasheet

Stock No: 9145519**RS Pro Clear Unreinforced PVC Hose**

Nominal Size	5 x 8mm
Internal Diameter	5.0 ± 0.25mm
External Diameter	8.0 ± 0.25mm
Length Tolerance	BS EN ISO 1307 (± 1%)
Maximum Working Pressure	N/A
Minimum Burst Pressure	N/A
Bend Radius	72mm
Working Temperature	-15°C to +60°C
Material	Flexible PVC
Material Softness	BSS45 FDA Approved
Flammability	Self-Extinguishing
Weight Per Meter	0.035Kg
Coil Weight	1.05Kg