

Cable gland - HC-B-G-M40-PLRBK - 1407672


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable gland, cable gland material: PA, PA, external cable diameter 19 mm ... 28 mm, shielding: no, connecting thread: Bayonet B plastic, color: black

RoHS

Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 776400
GTIN	4046356776400

Technical data

Dimensions

Wrench size, union nut	36 mm
External cable diameter	19 mm ... 28 mm

Ambient conditions

Degree of protection	IP66
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 100 °C

General

Type of the screw connection	M40
No. of conductors	1
Material	PA
Cable gland material	PA
Seal material	NBR
Cable seal material	NBR
Flammability rating according to UL 94	V0 / V2
Shielded	no
Thread type connection side	Bayonet B plastic
Tightening torque, union nut	7.50 Nm

Cable gland - HC-B-G-M40-PLRBK - 1407672

Technical data

General

Color	black
Assembly instructions	Bayonet locking max. 3x can be removed

Standards and Regulations


Flammability rating according to UL 94	V0 / V2
--	---------

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

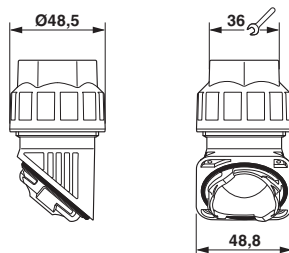

Dimensional drawing

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / EAC / GL / cULus Recognized

Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
---------------	--	---	---------


cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
----------------	--	---	---------

Cable gland - HC-B-G-M40-PLRBK - 1407672

Approvals

EAC			RU C- DE.AI30.B.01102
-----	---	--	--------------------------

GL		http://exchange.dnv.com/tari/	6196614 HH
----	---	---	------------

cULus Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	
------------------	---	---	--

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>