

Antenna - TC ANT MOBILE/GPS - 2903590

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Combined mobile phone GPS antenna with omnidirectional characteristic, 2 m antenna cable with SMA round plug (GSM/UMTS) and R-SMA round plug (GPS)



Key Commercial Data

Packing unit	1 STK
GTIN	
GTIN	4046356757546

Technical data

Dimensions

Height	23 mm
Diameter	76 mm

Ambient conditions

Degree of protection	IP69K
Ambient temperature (operation)	-40 °C ... 85 °C

General

With connecting cable	yes
Frequency range	850 MHz
	900 MHz
	1800 MHz
	1900 MHz
	2100 MHz
Gain	5 dBi (800/900 MHz)
	3 dBi (1800/1900 MHz)
	1 dBi (2100 MHz)
	25 dBi (GPS)
Connection method	SMA (male)

Antenna - TC ANT MOBILE/GPS - 2903590

Technical data

General


	RSMA (female)
Mounting type	Control cabinet

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Schematic diagram

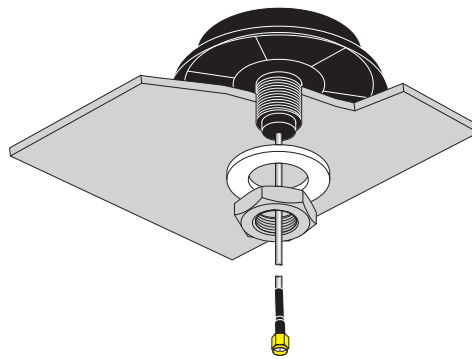

Mounting on the control cabinet

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>