

 

Proximity Sensor CRSMEO-4-K-LED-24

Part number: 161775
Classic

FESTO

Corrosion resistant,
with cable, without mounting kit CRSMB.

Modern alternatives can be found by entering the first four
characters of the type code in the search field.

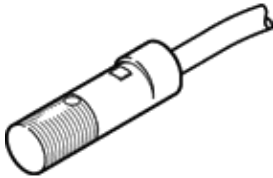

Data sheet

Feature	Value
Design	Round
Authorization	RCM Mark
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Materials note	Free of copper and PTFE
Measuring principle	Reed magnetic
Ambient temperature	-20 ... 60 °C
Switch output	with contact, bipolar
Switching element function	Normally open contact
Reproducibility of switching value	+/- 0,1 mm
Switch-on time	<= 0.5 ms
Switch-off time	0.03 ms
Max. output current	500 mA
Max. contact rating DC	10 W
Short circuit strength	No
Operating voltage range DC	12 ... 30 V
Polarity protected	No
Electrical connection	Cable 3-core
Cable length	2.5 m
Material cable sheath	TPE-O
Mounting type	with accessories
Product weight	70 g
Material housing	PP
Operating status display	Yellow LED
Ambient temperature with flexible cable installation	-5 ... 60 °C
Protection class	IP67