


Solenoid coil VACF-B-C1-5

Part number: 8030810

FESTO

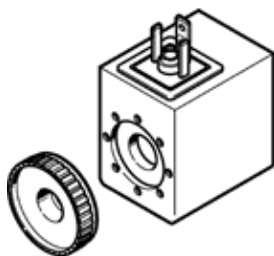

Data sheet

Feature	Value
Assembly position	Any
Duty cycle	100%
Insulation class	H
Characteristic coil data	12 V DC: 3.4 W
Permissible voltage fluctuation	+/- 10 %
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Medium temperature	-20 ... 50 °C
Protection class	IP65
Ambient temperature	-20 ... 50 °C
Authorization	c UL us - Recognized (OL)
Electrical connection	to EN 175301-803 Plug pattern type C to EN 175301-803
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material housing	PA Steel
Material solenoid coil	Copper Steel Thermoplastic
Material winding	Copper