 



Piloted check valve HGL-1/4-NPT

Part number: 34878

FESTO

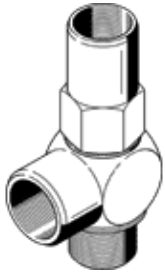

Data sheet

Feature	Value
Valve function	piloted non-return function
Pneumatic connection, port 1	NPT1/4-18
Pneumatic connection, port 2	NPT1/8-27
Mounting type	Threaded
Standard nominal flow rate	0 ... 490 l/min
Working pressure	0.3 ... 10 bar
Ambient temperature	-20 ... 80 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-20 ... 80 °C
Materials note	Conforms to RoHS
Material seals	NBR