


Socket connector MSSD-C

Part number: 34583

FESTO

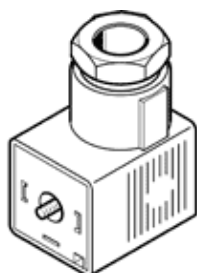

Data sheet

Feature	Value
Authorization	Germanischer Lloyd
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	22 g
Electrical connection	Plug socket angled Rectangular design, MSC Rectangular design, MSN1 Per DIN EN 175301-803 Plug pattern type A to EN 175301-803 3-pin
Cable gland connection	Pg9
Cable diameter	6 ... 8 mm
Nominal conductor cross-section	$\leq 1.5 \text{ mm}^2$
Protection class	IP65
Ambient temperature	-25 ... 90 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Materials note	Conforms to RoHS
Material housing	Plastic
Housing color	Black