


# Socket connector MSSD-C-M16

Part number: 539709

FESTO

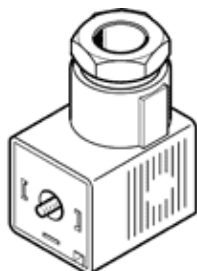

## Data sheet

Feature	Value
Connection frequency	50
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	38 g
Electrical connection	Plug socket angled Cubic design Per DIN EN 175301-803 Plug pattern type A to EN 175301-803 3-pin
Cable gland connection	M16
Permissible cable diameter	6 ... 8 mm
Terminal cross-section	1.5 mm <sup>2</sup>
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 115 °C
Materials note	Conforms to RoHS
Material housing	PA-reinforced
Material seals	HNBR