


Socket connector MSSD-EB-M12

Part number: 539712

FESTO

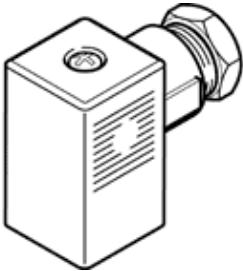

Data sheet

Feature	Value
Connection frequency	50
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	11 g
Electrical connection	Plug socket angled Cubic design Per DIN EN 175301-803 Plug pattern type C to EN 175301-803 3-pin
Cable gland connection	M12
Permissible cable diameter	4 ... 6 mm
Terminal cross-section	1.5 mm ²
Protection class	IP65 to IEC 60529
Ambient temperature	-40 ... 125 °C
Material housing	PA-reinforced
Material seals	HNBR