


Socket connector MSSD-V

Part number: 33295

FESTO

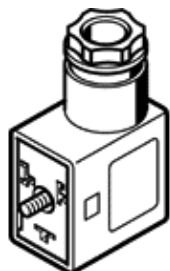

Data sheet

Feature	Value
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	18 g
Electrical connection	Plug socket Plug socket angled Rectangular design, MSV Per DIN EN 175301-803 Plug pattern type B to EN 175301-803 3-pin
Cable gland connection	Pg9
Cable diameter	6 ... 8 mm
Nominal conductor cross-section	$\leq 1.5 \text{ mm}^2$
Protection class	IP65
Ambient temperature	-25 ... 90 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Material housing	Plastic
Housing color	Black