


# Multi-pin CPV10-VI-P4-M7-C

Part number: 538808

FESTO

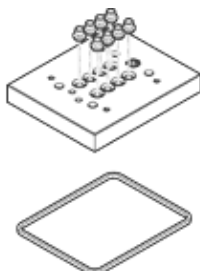

## Data sheet

Feature	Value
ATEX category Gas	II 2G
Explosion ignition protection type Gas	Ex e II
ATEX category Dust	II 2D
Explosion ignition protection type Dust	Ex tD A21 IP65
Explosion protection certification outside the EU	EPL Db (IEC-EX) EPL Gb (IEC-EX)
Explosion-proof ambient temperature	-10°C ≤ Ta ≤ +60°C
Certificate issuing department	IECEX TUR 12.0002X TÜV 06 ATEX 7334 X
CE symbol (see declaration of conformity)	according to EU-Ex protection guideline (ATEX)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Materials note	Free of copper and PTFE Conforms to RoHS
Material seals	NBR
Material plate	Wrought Aluminum alloy