


# Plug socket with cable KMEB-1-24-2,5-LED

Part number: 151688

★ Core product range

FESTO

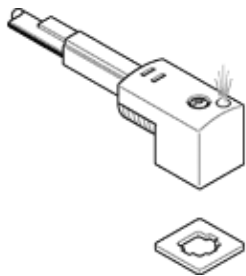

## Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	125 g
Electrical connection	Plug socket angled Per DIN EN 175301-803 Plug pattern type C to EN 175301-803 3-pin
Nominal operating voltage DC	24 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	5.2 mm
Cable structure	3x0,5
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PA66-GF30
Material electrical contact	Bronze