


# Multiple distributor QSLV6-1/8-8

Part number: 153244

FESTO

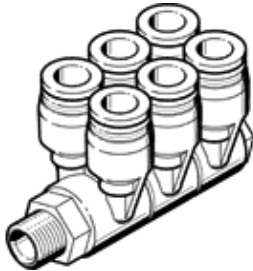

## Data sheet

Feature	Value
Size	Standard
Nominal size	4 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Design structure	Push/pull principle
Container size	1
Operating pressure complete temperature range	-0.95 ... 6 bar
Temperature dependent working pressure	-0.95 ... 14 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 80 °C
Maritime classification	see certificate
Product weight	71 g
Number of outputs	6
Number of supply lines	1
Pneumatic connection, port 1	Male thread R1/8
Pneumatic connection, port 2	For tubing outside diameter 8 mm
color of release ring	blue
Materials note	Conforms to RoHS
Material housing	PBT
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive