


**Vacuum filter**  
**VAF-DB-1/4**  
 Part number: 547261

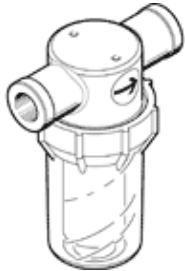

**Data sheet**

<b>Feature</b>	<b>Value</b>
Assembly position	Vertical
Grade of filtration	80 µm
Working pressure	-0.95 ... 0 bar
Note on working pressure	Only for application in open vacuum systems
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-5 ... 50 °C
Max. tightening torque	8.7 Nm
Product weight	71 g
Mounting type	Line installation with wall/surface fixing
Pneumatic connection	G1/4
Vacuum connection	G1/4
Materials note	Contains PWIS substances Conforms to RoHS
Material seals	NBR
Material filter	PE
Material housing	PP reinforced
Material bowl	PA
Ejector pulse suitability	≤ 7 bar