

# Reducing adapter - REDUC-M-KV-M40/M32 - 1647640

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Reducing adapter, M40 on M32, incl. O-ring

## Product Description

Reduced M40 to M32



## Key Commercial Data

Packing unit	10 STK
GTIN	 4 017918 941543
GTIN	4017918941543

## Technical data

### Dimensions

Length	11.5 mm
Length without connecting thread	3.5 mm
Connecting thread diameter	40 mm
Hexagon angular dimension	43 mm
Length of the connecting thread	8 mm

### Ambient conditions

Degree of protection	IP65 (Depends on the screw connection used)
Ambient temperature (operation)	-20 °C ... 80 °C

### General

Material	Brass, nickel-plated
Cable gland material	Nickel-plated brass
Outer thread	M40
Internal thread	M32
Torque	11 Nm ... 12 Nm
Color	silver

# Reducing adapter - REDUC-M-KV-M40/M32 - 1647640

## Technical data

### Standards and Regulations


Halogen-free	no
--------------	----

### Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings

Dimensional drawing

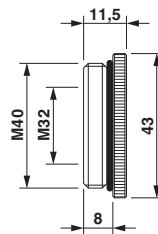

Dimensional drawing

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>