


Electrical module VMPA1-FB-EMS-D2-8

Part number: 543331

FESTO

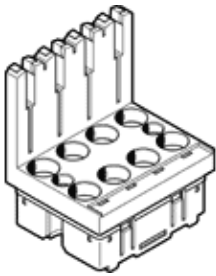

Data sheet

| Feature | Value |
|--|--|
| Diagnosis | <ul style="list-style-type: none">- Condition Monitoring- Wire break per solenoid coil- Short circuit of valves- Undervoltage of valves |
| Max. number of valve positions | 4 |
| Max. number of solenoid coils | 8 |
| Intrinsic current consumption at load voltage | 3 mA |
| Intrinsic current consumption at operating voltage | 8 mA |
| Nominal breakaway current per solenoid coil | 58 mA up to 24 ms |
| Nominal current with current reduction | 9 mA after 24 ms |
| Corrosion resistance classification CRC | 1 - Low corrosion stress (when installed) |
| Product weight | 20 g |
| Material housing | POM |
| Materials note | Conforms to RoHS |