


# Subbase VMPA2-FB-AP-2-1

Part number: 538000

FESTO

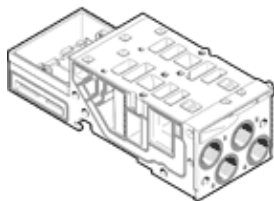

## Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Grid dimension	21 mm
Max. number of valve positions	2
Working pressure	-0.9 ... 10 bar
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-5 ... 50 °C
Product weight	185 g
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast