


**Distributor block**  
**FR-4-3/8-B**  
Part number: 6703

**FESTO**

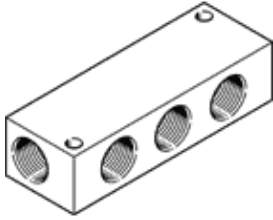

**Data sheet**

<b>Feature</b>	<b>Value</b>
Nominal size	15 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-10 ... 80 °C
Product weight	75 g
Number of outputs	3
Number of supply lines	1
Pneumatic connection, port 1	Female thread G3/8
Pneumatic connection, port 2	Female thread G3/8
Materials note	Conforms to RoHS
Material housing	Aluminum die cast