


coupling socket

KD3-1/8-A

Part number: 2142

FESTO

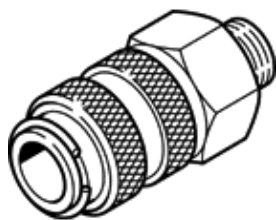

Data sheet

Feature	Value
Nominal size	4.95 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	563 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	5 Nm
Tolerance for nominal tightening torque	± 15 %
Product weight	28 g
Pneumatic connection, port 1	Male thread G1/8
Materials note	Conforms to RoHS