


**Plug
SEA-GS-7**
Part number: 18666

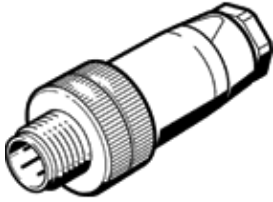

Data sheet

Feature	Value
Based on the standard	EN 61076-2-101 EN 61984
Mounting type	with threaded sleeve
Assembly position	Any
Product weight	17 g
Electrical connection	Plug pattern type A to EN 175301-803 M12x1 4-pin Straight plug / screw terminal
Operating voltage range DC	<= 250 V
Operating voltage range AC	<= 250 V
Acceptable current load at 40°C	4 A
Surge strength	2.5 kV
Cable gland connection	Pg7
Permissible cable diameter	4 ... 6 mm
Terminal cross-section	0.75 mm ²
Protection class	IP67
Ambient temperature	-40 ... 85 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	PBT
Housing color	Black
Material of union nut	PBT
Material electrical contact	Brass White bronze coated