


Quick connector CK-1/8-PK-3

Part number: 3563

FESTO

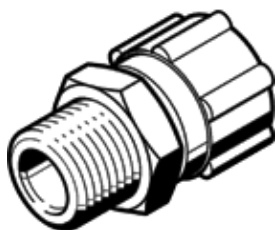

Data sheet

Feature	Value
Nominal size	2 mm
Type of seal on screw-in stud	Sealing ring
Assembly position	Any
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	-10 ... 60 °C
Maritime classification	see certificate
Pneumatic connection, port 1	Male thread G1/8
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Conforms to RoHS
Material housing	Aluminum