


# Push-in sleeve QSH-1/4-U

Part number: 153819

FESTO

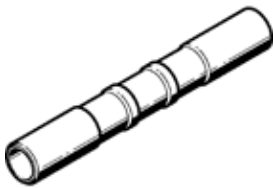

## Data sheet

Feature	Value
Assembly position	Any
Container size	1
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Maritime classification	see certificate
Product weight	1 g
Pneumatic connection, port 1	Push-in sleeve QS-1/4"
color of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PBT